




QUIK-LOQ™

Rapid Latching I/O Systems

NorComp QUIK-LOQ™ 8P1P Series are engineered as a high performance cost-effective solution for applications requiring quick connect / disconnect in markets including medical devices control systems and test & measurement. The series is available in a wide range of pin counts & colors. It can be combined with NorComp's value added cable assembly solutions and is fully intermateable with existing industry solutions.

FEATURES & BENEFITS

- IP50 Rated
- 2000 Mating Cycles
- Haptic Feedback When Mating
- Positive Locking: Prevents Accidental Disconnection
- Available in 2 to 14 Way Variants
- Temperature Range: 0°C/+80°C
- Push-Pull Latch and Release Mechanism
- Available in 6 Different Color Codes to Increase Usability
- Value Added Cable Assembly Solutions Available

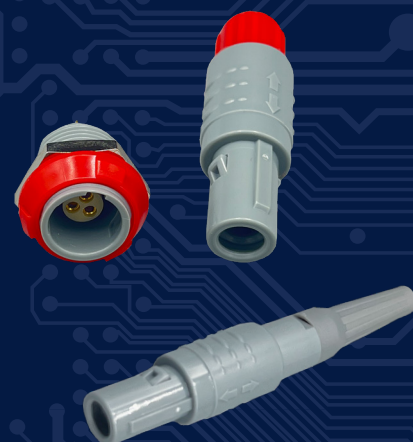

NORCOMP

Plastic Push Pull Connectors

QUIK-LOQ™

High Performance
Push Pull
Connector Systems

Series	Cable Mount	Panel Mount		
		Solder Cup	Vertical	Right Angle
8P1P	2,3,4,5,6,7,8 9,10,14 (Male Only) Flexible Boot or Plastic Nut	2,3,4,5,6,7,8 9,10,14 (Female Only) Front Mount or Rear Mount (Dual Nut)	2,3,4,5,6,7,8 9,10,14 (Female Only) Front Mount or Rear Mount (Dual Nut)	2,3,4,5,6,7,8 9,10,14 (Female Only) Rear Mount (Dual Nut)
Colors				
Grey (standard)	✓	✓	✓	✓
Blue	✓	✓	✓	✓
Yellow	✓	✓	✓	✓
Black	✓	✓	✓	✓
Red	✓	✓	✓	✓
Green	✓	✓	✓	✓



Boots



Nuts



Right Angle



Cable Mount Booted



Solder Cup Fixed Nut



Vertical Mount Fixed Nut



Cable Mount



Solder Cup Two Nut



Vertical Mount Two Nut

...robust & reliable
quick-locking
mechanism

