


High Durability USB A 2.0

USB1130

- Ⓜ Tested to over 10,000 mating cycle
6x the standard of USB A 2.0
- Ⓜ High-grade stainless steel shell
- Ⓜ Right-angle mount perfect for
high-traffic applications
- Ⓜ 3A current rating - double the
standard of USB A 2.0

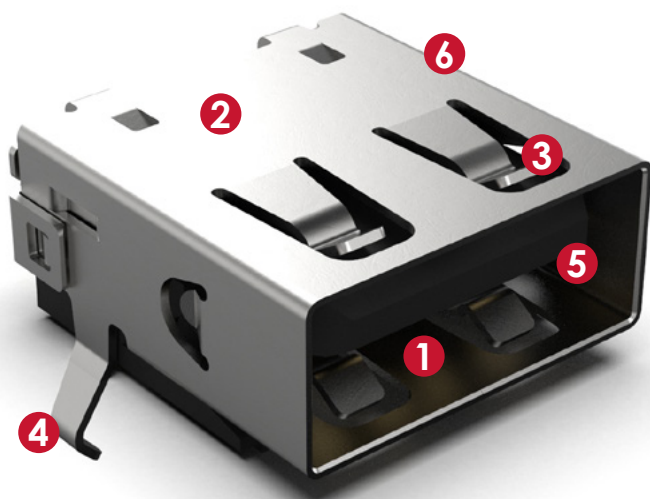

- 1 USB A interface
- 2 High grade SUS304 shell
- 3 6 retention tabs
- 4 2 sprung shell stakes
- 5 USB 3.0 with 9 contacts
- 6 14.16mm shell depth

Vital Stats

Mating Cycles

10,000

Shell Material

Stainless Steel

Current Rating

3 Amp

USB Specification

2.0

Profile Height

6.99mm

No. of Contacts

4

Applications

Public Transport
In-vehicle Entertainment
Computer Laptops
Charging Stations
Consumer Electronics



gct.co/connector/usb1130