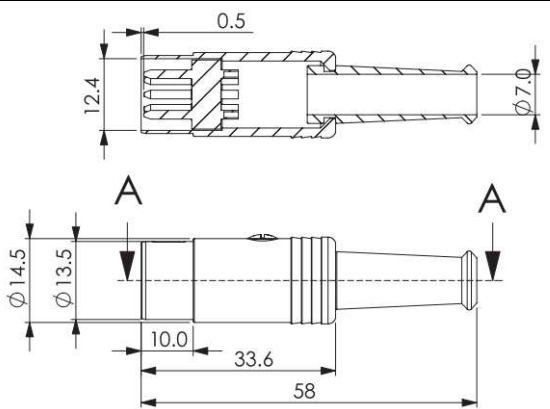
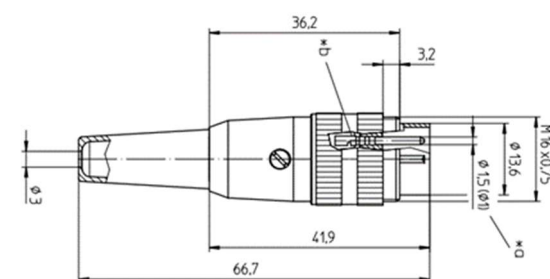


Circular Connector Selection Guide

Choose By Size	Choose by attributes			Choose by features
Series 01 DIN circular connectors 13.2 mm diameter 	01 Series DIN Mount: PCB Flange Cable Terminals: Solder Contact pin CuZn, silver-plated	03 Series IP40 Mount: PCB Flange Cable Terminals: Solder Crimp Contact pin CuZn, silver-plated	03 Series IP68 Mount: PCB Flange Cable Terminals: Solder Crimp Contact pin CuZn, silver-plated, Gold plated	- Shielding 360° shielding or No shield - Poles 3-8, some 12 & 14-pole options - Signal & load currents From 1A to 5A - Voltage rating 100 V/300 V depending on pin configuration - Certifications and ratings AISG IEC 61076-2-106 IEC 60130-9 UL94
Series 03 M16 circular connectors 16 mm diameter; threaded 	Insulating body: PA, V-0 according to UL94 Housing CuZn, nickel-plated	Insulating body: PA GF, V-0 according to UL94 Housing CuZn, nickel-plated	Insulating body: PA GF, V-0 according to UL94 Housing Zinc Die Cast with nickel finish	