


Ultrasound Scanning System

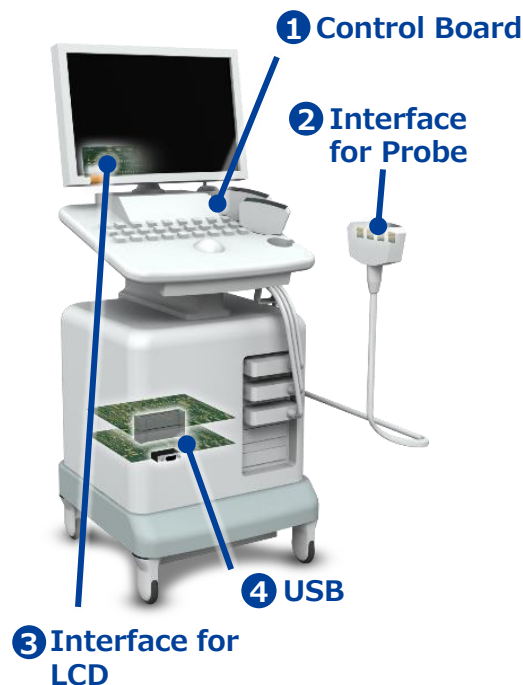

1 Control Board

Board-to-Board

FunctionMAX™



FX18

16Gbps High Speed Transmission
Pitch : 0.8mm
No. of Pos.: 40-180

FunctionMAX™



ER8


16Gbps High Speed Transmission
Pitch : 0.8mm
No. of Pos.: 10-140



EX80

Shielded Mezzanine
Pitch : 0.6mm
No. of Pos.: 54, 100

Shielded FFC

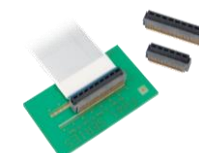

FH41

3.75Gbps High Speed Transmission
Pitch : 0.5mm



FH48

3.75Gbps High Speed Transmission
Vertical Connection
Pitch : 0.5mm



FH28K

Pitch : 0.5mm
No. of Pos.: 10-80

FPC

2 Interface for Probe

Board-to-Board


FunctionMAX™



FX10

Pitch : 0.5mm
Stacking Height : 4-8mm
No. of Pos.: 80-168

FunctionMAX™

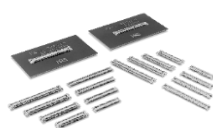

FX11


Pitch : 0.5mm
Stacking Height : 2-3mm
No. of Pos.: 68-140



EX

Low Insertion
No. of Pos.: 280

Micro Coaxial

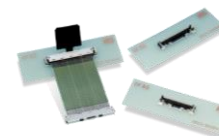


DF80

No. of Pos.: 30, 40, 50
Applicable Cable :
32-36 AWG (Discreet Cable)
40-46 AWG (Micro Coaxial)



DF81

No. of Pos.: 30, 40, 50
Applicable Cable :
34-36 AWG (Discreet Cable)
40-46 AWG (Micro Coaxial)

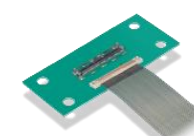

DF36

No. of Pos.: 15-50
Applicable Cable :
42-46 AWG (Micro Coaxial)

3 Interface for LCD

Wire-to-Board



DH

2.5Gbps High Speed Transmission
Pitch : 1.0mm

4 USB

Wire-to-Board



GT17H/HN

1Gbps High Speed Transmission
USB2.0