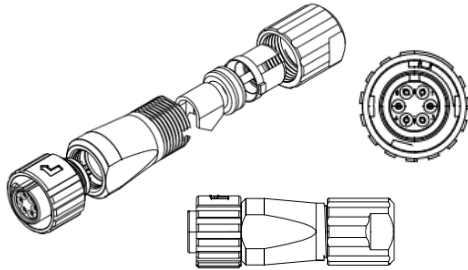
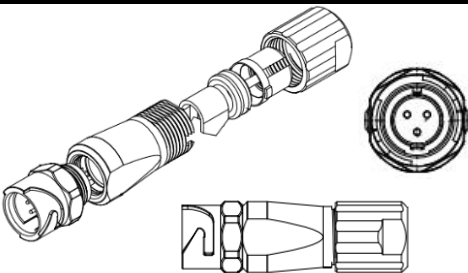
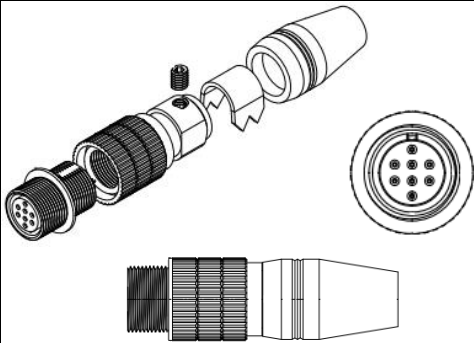
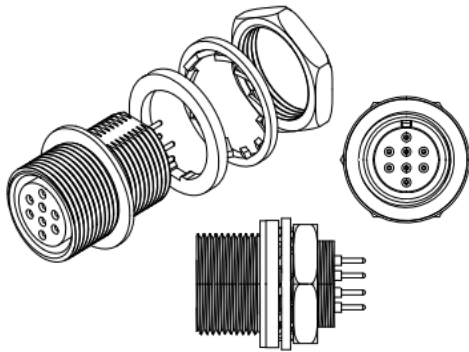
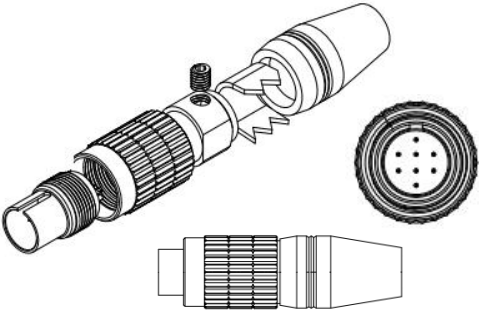
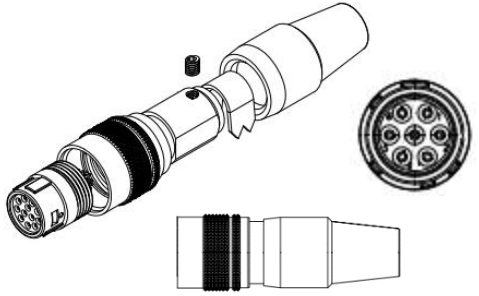
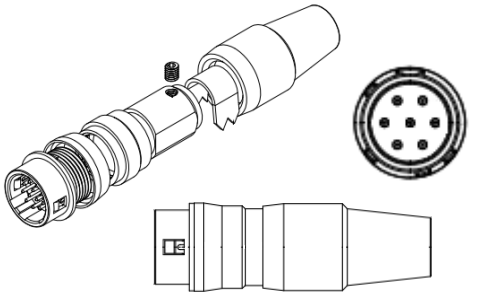


Waterproof Push-Pull Connectors

Quick Reference Guide #2		
SD-MMNXX-FFBBL-SX0-000		
SD-MMN03-FFBBL-S70-000 SD-MMN06-FFBBL-S70-000	Metal housing, metal nut, DIN, 03 and 06 positions, female connector, female contact, bayonet/twist lock mating, molding cable without strain relief, straight back shell, solder type, IP67 rating, no cable	
SD-MMNXX-MMBBL-SX0-000		
SD-MMN03-MMBBL-S70-000 SD-MMN06-MMBBL-S70-000	Metal housing, metal nut, DIN, 03 and 06 positions, male connector, male contact, bayonet/twist lock mating, molding cable without strain relief, straight back shell, solder type, IP67 rating, no cable	
SD-PNLXX-FFTAL-SX0-000		
SD-PNL04-FFTAL-S70-000 SD-PNL06-FFTAL-S70-000 SD-PNL08-FFTAL-S70-000	Plastic housing, without nut, M12 (L coding), multiple positions (04, 06, 08), female connector, female contact, thread/screw mating, molding cable with strain relief, straight back shell, solder type, IP67 rating, no cable	
SD-PNLXX-FFTRH-PX0-000		
SD-PNL04-FFTRH-P70-000 SD-PNL06-FFTRH-P70-000 SD-PNL08-FFTRH-P70-000	Plastic housing, without nut, M12 (L coding), multiple positions (04, 06, 08), female connector, female contact, thread/screw mating, panel rear mount, hexagonal panel base, 180° PCB type, IP67 rating, no cable	

Waterproof Push-Pull Connectors

SD-PNLXX-MMTAL-SX0-000		
SD-PNL04-MMTAL-S70-000 SD-PNL06-MMTAL-S70-000 SD-PNL08-MMTAL-S70-000	Plastic housing, without nut, M12 (L coding), multiple positions (04, 06, 08), male connector, male contact, thread/screw mating, molding cable with strain relief, straight back shell, solder type, IP67 rating, no cable	
SD-PNNXX-FFLAL-SX0-000		
SD-PNN04-FFLAL-S70-000 SD-PNN05-FFLAL-S70-000 SD-PNN06-FFLAL-S70-000 SD-PNN07-FFLAL-S70-000 SD-PNN10-FFLAL-S70-000 SD-PNN12-FFLAL-S70-000	Plastic housing, without nut, DIN, multiple positions (04, 05, 06, 07, 10, 12), female connector, female contact, shell lock mating, molding cable with strain relief, straight back shell, solder type, IP67 rating, no cable	
SD-PNNXX-MMLAL-SX0-000		
SD-PNN04-MMLAL-S70-000 SD-PNN05-MMLAL-S70-000 SD-PNN06-MMLAL-S70-000 SD-PNN07-MMLAL-S70-000 SD-PNN10-MMLAL-S70-000 SD-PNN12-MMLAL-S70-000	Plastic housing, without nut, DIN, multiple positions (04, 05, 06, 07, 10, 12), male connector, male contact, shell lock mating, molding cable with strain relief, straight back shell, solder type, IP67 rating, no cable	
SD-PNNXX-MMLRH-PX0-000		
SD-PNN04-MMLRH-P70-000 SD-PNN05-MMLRH-P70-000 SD-PNN06-MMLRH-P70-000 SD-PNN07-MMLRH-P70-000 SD-PNN10-MMLRH-P70-000 SD-PNN12-MMLRH-P70-000	Plastic housing, without nut, DIN, multiple positions (04, 05, 06, 07, 10, 12), male connector, male contact, shell lock mating, panel rear mount, hexagonal panel base, 180° PCB type, IP67 rating, no cable	