 
 
 
 
 
 
 
 
 
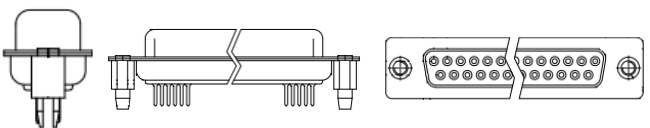
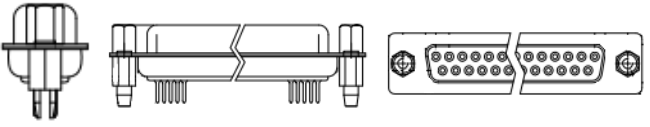
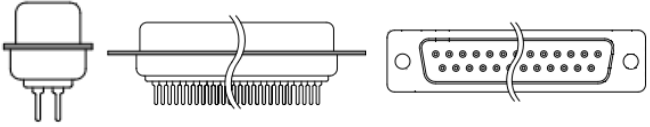
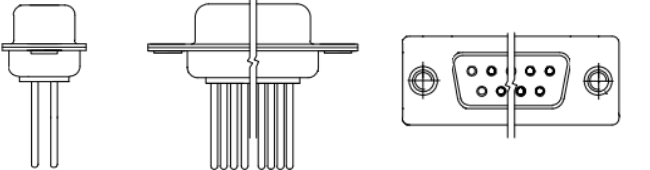
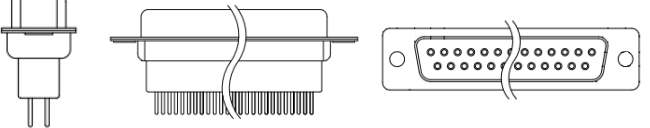
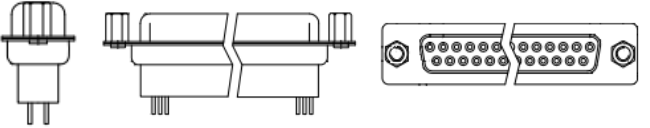
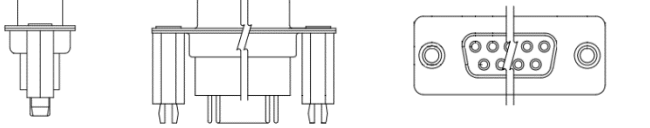
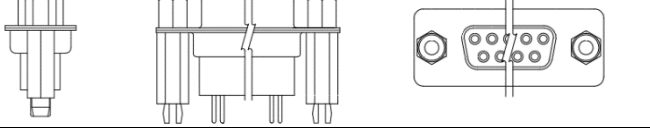
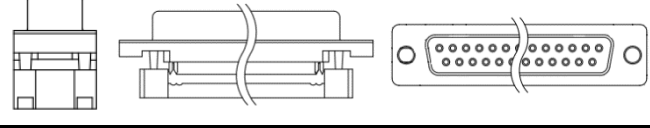


 
 
 
 
 
 
 
 
 
 
 
 
 
 
 
 
D-Subminiature Sockets

Quick Reference Guide #4			
D-Sub Flush Mount Straight PCB Socket (DXXX-SA-M1 and DXXX-SA-M2)			
DE09-SA-M1 DA15-SA-M1 DB25-SA-M1 DC37-SA-M1	Multiple contacts (9, 15, 25, 37), through hole mounting		
DE09-SA-M2 DA15-SA-M2 DB25-SA-M2 DC37-SA-M2	Multiple contacts (9, 15, 25, 37), #4-40 threaded mounting holes		
D-Sub Solder Cup Socket (DXXX-SD, DXXX-SD-SL, DXXX-SD-JS, and DXXX-SD-MC)			
DE09-SD DA15-SD DB25-SD DC37-SD	Multiple contacts (9, 15, 25, 37), .120" [3.05mm] mounting holes		
DE09-SD-SL DA15-SD-SL DB25-SD-SL DC37-SD-SL	Multiple contacts (9, 15, 25, 37), bottom side riveted #4-40 clinch nuts		
DE09-SD-JS DA15-SD-JS DB25-SD-JS DC37-SD-JS	Multiple contacts (9, 15, 25, 37), top side riveted #4-40 jackscrews		
DE09-SD-MC DA15-SD-MC DB25-SD-MC DC37-SD-MC	Multiple contacts (9, 15, 25, 37), .120" [3.05mm] mounting holes, machined pin		
D-Sub Standard Profile Straight PCB Socket – Standard Tail Length (DXXX-ST-1, DXXX-ST-1-SL, DXXX-ST-1-JS, DXXX-ST-1-BL, DXXX-ST-1-BL-JS, and DXXX-ST-1-MC)			
DE09-ST-1 DA15-ST-1 DB25-ST-1 DC37-ST-1	Multiple contacts (9, 15, 25, 37), .120" [3.05mm] mounting holes		
DE09-ST-1-SL DA15-ST-1-SL DB25-ST-1-SL DC37-ST-1-SL	Multiple contacts (9, 15, 25, 37), bottom side riveted #4-40 clinch nuts		
DE09-ST-1-JS DA15-ST-1-JS DB25-ST-1-JS DC37-ST-1-JS	Multiple contacts (9, 15, 25, 37), top side riveted #4-40 jackscrews		

D-Subminiature Sockets

DE09-ST-1-BL DA15-ST-1-BL DB25-ST-1-BL DC37-ST-1-BL	Multiple contacts (9, 15, 25, 37), riveted #4-40 standoffs, board locks	
DE09-ST-1-BL-JS DA15-ST-1-BL-JS DB25-ST-1-BL-JS DC37-ST-1-BL-JS	Multiple contacts (9, 15, 25, 37), riveted #4-40 jackscrews and standoffs, board locks	
DE09-ST-1-MC DA15-ST-1-MC DB25-ST-1-MC DC37-ST-1-MC	Multiple contacts (9, 15, 25, 37), .118" [3.00mm] mounting holes, machined pin	
D-Sub Standard Profile Straight PCB Socket – Wire Wrap Tail (DXXX-ST-2)		
DE09-ST-2 DA15-ST-2 DB25-ST-2 DC37-ST-2	Multiple contacts (9, 15, 25, 37), .120" [3.05mm] mounting holes	
D-Sub High Profile Straight PCB Socket – Standard Tail Length (DXXX-SE-1, DXXX-SE-1-JS, DXXX-SE-1-BL, and DXXX-SE-1-BL-JS)		
DE09-SE-1 DA15-SE-1 DB25-SE-1 DC37-SE-1	Multiple contacts (9, 15, 25, 37), .120" [3.05mm] mounting holes	
DE09-SE-1-JS DA15-SE-1-JS DB25-SE-1-JS DC37-SE-1-JS	Multiple contacts (9, 15, 25, 37), top side riveted #4-40 jackscrews	
DE09-SE-1-BL DA15-SE-1-BL DB25-SE-1-BL DC37-SE-1-BL	Multiple contacts (9, 15, 25, 37), riveted #4-40 standoffs, board locks	
DE09-SE-1-BL-JS DA15-SE-1-BL-JS DB25-SE-1-BL-JS DC37-SE-1-BL-JS	Multiple contacts (9, 15, 25, 37), riveted #4-40 jackscrews and standoffs, board locks	
D-Sub Flat Cable IDC Socket (DXXX-SF-M1 and DXXX-SF-M2)		
DE09-SF-M1 DA15-SF-M1 DB25-SF-M1 DC37-SF-M1	Multiple contacts (9, 15, 25, 37), metal shell, .130" [3.30mm] mounting holes	

D-Subminiature Sockets

DE09-SF-M2 DA15-SF-M2 DB25-SF-M2 DC37-SF-M2	Multiple contacts (9, 15, 25, 37), metal shell, #4-40 threaded flush inserts	  
D-Sub Right Angle Socket – .318" [8.08mm] Footprint (DXXX-SL-24 and DXXX-SL-25)		
DE09-SL-24 DA15-SL-24 DB25-SL-24 DC37-SL-24	Multiple contacts (9, 15, 25, 37), forked board locks, #4-40 flush threaded inserts	  
DE09-SL-25 DA15-SL-25 DB25-SL-25 DC37-SL-25	Multiple contacts (9, 15, 25, 37), forked board locks, #4-40 flush threaded inserts with removable jackscrews	  
D-Sub Right Angle Socket – .197" [5.00mm] Slimline (DXXX-SN-24 and DXXX-SN-25)		
DE09-SN-24 DB25-SN-24	Multiple contacts (9 and 25), forked board locks, #4-40 flush threaded inserts	  
DE09-SN-25 DA15-SN-25	Multiple contacts (9 and 15), forked board locks, #4-40 flush threaded inserts with removable jackscrews	  
D-Sub Crimp and Poke Socket (DXXX-SR and DXXX-SR-SL)		
DE09-SR DA15-SR DB25-SR DC37-SR	Multiple contacts (9, 15, 25, 37), .120" [3.05mm] mounting holes	  
DE09-SR-SL DA15-SR-SL DB25-SR-SL DC37-SR-SL	Multiple contacts (9, 15, 25, 37), bottom side riveted #4-40 clinch nuts	