
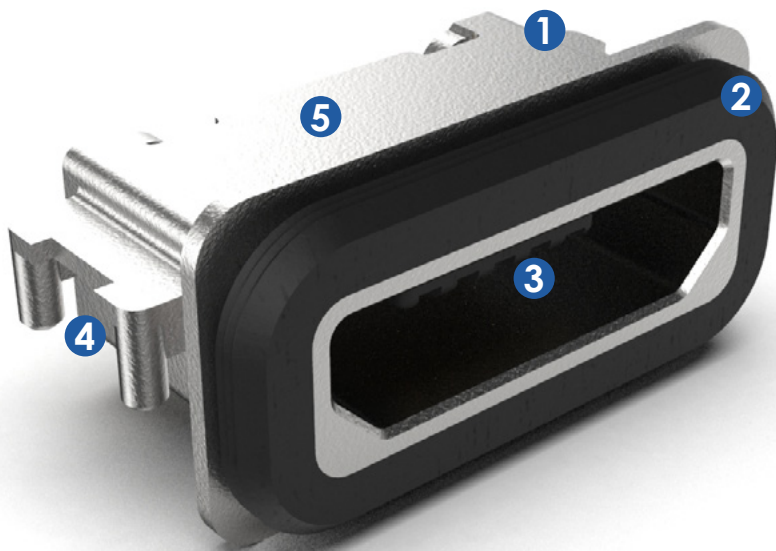


aquanex[®] Micro USB

USB3500

- Water-and-dust-proof
- Full IP67 Rating
- Metal Injection Moulded single-piece stainless steel shell

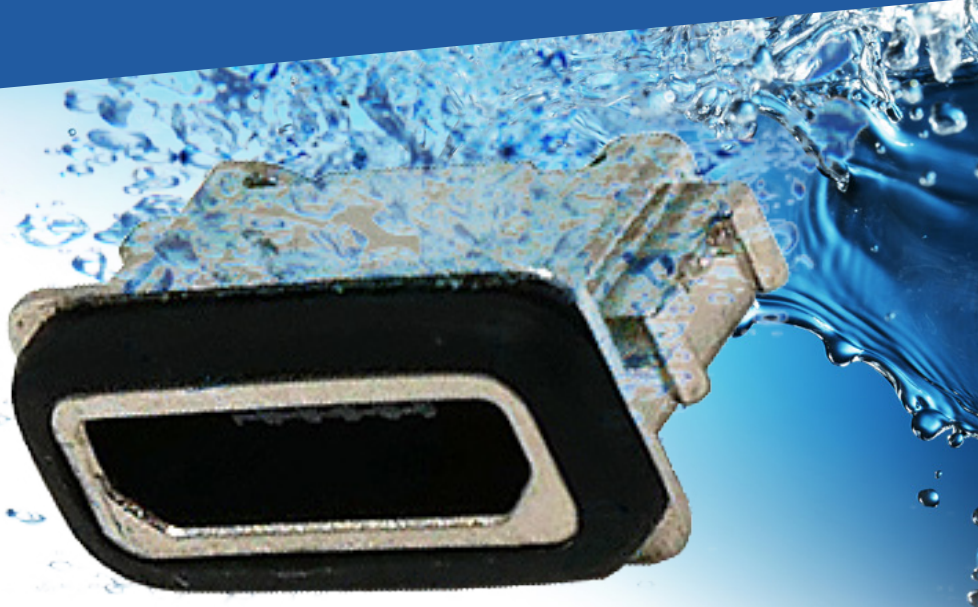

Vital Stats

Interface	IP Rating
USB Micro B	IP67
No. of Contacts	Mating Cycles
5	10,000
USB Specification	Profile Above PCB
2.0	4.90mm

- 1 Horizontally mid-mounted socket
- 2 Silicone gasket to seal against panel
- 3 USB Micro B interface with 5 contacts
- 4 4 through-hole shell stakes
- 5 Metal Injection Moulded shell

Applications

Pool & Spa Controls
Hydroponics
Home Security
Consumer Electronics
Medical Equipment



gct.co/connector/usb3500