

SPLIT PROCESS SIGNALS

FOR MONITORING + VALIDATION

APD 4930

APD 4930 D



IsoSplitter® Signal Splitter & Isolator

Standard: 4-20 mA Input and Two 4-20 mA Outputs
Custom VDC, $\pm$ VDC, mA/VDC Ranges Available


- Convert & Isolate 1 DC Input to 2 DC Outputs
- Sink/Source Input, Optional Sinking Output
- Universal Power: 85-265 VAC, 60-300 VDC
- D option: 9-30 VAC/VDC power
- 6 Year Warranty



Tech Specs

- ▶ Superior 4-way optical isolation eliminates noise & ground loops
- ▶ Space-saving 22.5mm housing
- ▶ LoopTracker® output LEDs
- ▶ Output test/manual override for each channel
- ▶ Independently configured voltage or current outputs

Process
Signal
Input

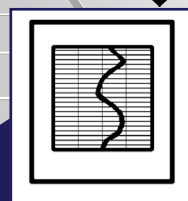

PLC

Available at

DigiKey