

Wire to Wire Receptacle housing single row	Single Row DMT-1-XX (2-12 positions)	
Contact options	DMT-A-C-F-T-R, 26-30 AWG Tin plated DMT-B-C-F-G-R, 26-30 AWG Tin plated DMT-A-C-F-G-R, 26-30 awg Gold plated DMT-B-C-F-T-R, 20-24 AWG Gold plated	

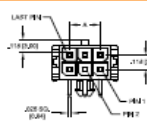
 
Wire to PCB Receptacle housing single row	Single Row DMT-1-XX (2-12 positions)	
Contact options	DMT-A-C-F-T-R 26-30 AWG Tin plated DMT-B-C-F-G-R 26-30 AWG Tin plated DMT-A-C-F-G-R 26-30 AWG Gold plated DMT-B-C-F-T-R 20-24 AWG Gold plated	

Wire to Wire Plug housing dual row	Dual Row DMU-2-XX-NPM (free hanging 2-24 positions) or DMU-2-XX-T panel mount 2-24 positions	
Contact options	DMU-A1-C-M-T-R, 26-30 AWG Tin plated DMUB1-C-M-T-R, 20-24 AWG Tin plated DMU-A-C-M-G-R, 26-30 AW Gold plated DMU-B-C-M-G-R, 20-23 AWG Gold plated	

 
 
 
 
Wire to Wire plug housing single row	Single Row DMU-1-XX-NPM (free hanging [2-12 positions]) or DMU-1-XX-T panel	
Contact options	DMU-A1-C-M-T-R, 26-30 AWG Tin plated DMUB1-C-M-T-R, 20-24 AWG Tin plated DMU-A-C-M-G-R, 26-30 AWG Gold plated DMU-B-C-M-G-R, 20-24 AWG Gold plated	

PCB Header Right angle single row	Single Row DML-1-XX-A-H-G-A-BL [right angle through hole] Gold plating boardlocks DML-1-XX-A1-H-T-A-TSMT-TR [right angle, true SMT] Tin plated hi temp DML-1-XX-A2-H-T-A [right angle through hold] Tin plated hi temp, boardlocks	
Contact options	DMT-A-C-F-T-R 26-30 AWG Tin plated DMT-B-C-F-G-R 26-30 AWG Tin plated DMT-A-C-F-G-R 26-30 AWG Gold plated DMT-B-C-F-T-R 20-24 AWG Gold plated	

Wire to Wire Receptacle housing dual row	Dual Row DMT-2-XX (2-24 positions)	
Contact options	DMT-A-C-F-T-R, 26-30 AWG Tin plated DMT-B-C-F-G-R, 26-30 AWG Tin plated DMT-A-C-F-G-R, 26-30 AWG Gold plated DMT-B-C-F-T-R, 20-24 AWG Gold plated	

PCB Header right angle dual row	Dual Row DML-XX-A1-H-T-SMT-BL [hi temp] RA SMT Tin plated with boardlocks DML-XX-A4-H-T-A [hi temp] RA through hole with boardlocks DML-XX-A-H-G-A [hi temp] RA through hole Gold plated with boardlocks DML-XX-A-H-G-SMT-BL-TR [hi temp] RA SMT Gold plated with boardlocks	 
Contact options	DMT-A-C-F-T-R 26-30 AWG Tin plated DMT-B-C-F-G-R 26-30 AWG Tin plated DMT-A-C-F-G-R 26-30 AWG Gold plated DMT-B-C-F-T-R 20-24 AWG Gold plated	

Wire to PCB Receptacle housing dual row	Dual Row DMT-2-XX (2-24 positions) 
Contact options	DMT-A-C-F-T-R 26-30 AWG Tin plated DMT-B-C-F-G-R 26-30 AWG Tin plated DMT-A-C-F-G-R 26-30 AWG Gold plated DMT-B-C-F-T-R 20-24 AWG Gold plated

PCB Header Vertical row	Dual Row DML-XX-A-V-GA [hi temp] Gold plated through hole DML-XX-A-V-G-A-6-TR [hi temp] Gold plated through hole DML-XX-A-V-G-SMT-BL-PP-TR [hi temp] Gold plated SMT DML-XX-A-V-MT-TSMT-PP-TR [hi temp] matte tin SMT	  
Contact options	DMT-A-C-F-T-R 26-30 AWG Tin plated DMT-B-C-F-G-R 26-30 AWG Tin plated DMT-A-C-F-G-R 26-30 AWG Gold plated DMT-B-C-F-T-R 20-24 AWG Gold plated	

Wire to PCB Receptacle housing dual row	Dual Row DMT-2-XX (2-24 positions)	
Contact options	DMT-A-C-F-T-R 26-30 AWG Tin plated DMT-B-C-F-G-R 26-30 AWG Tin plated DMT-A-C-F-G-R 26-30 AWG Gold plated DMT-B-C-F-T-R 20-24 AWG Gold plated	