



SL Power External Power Supplies

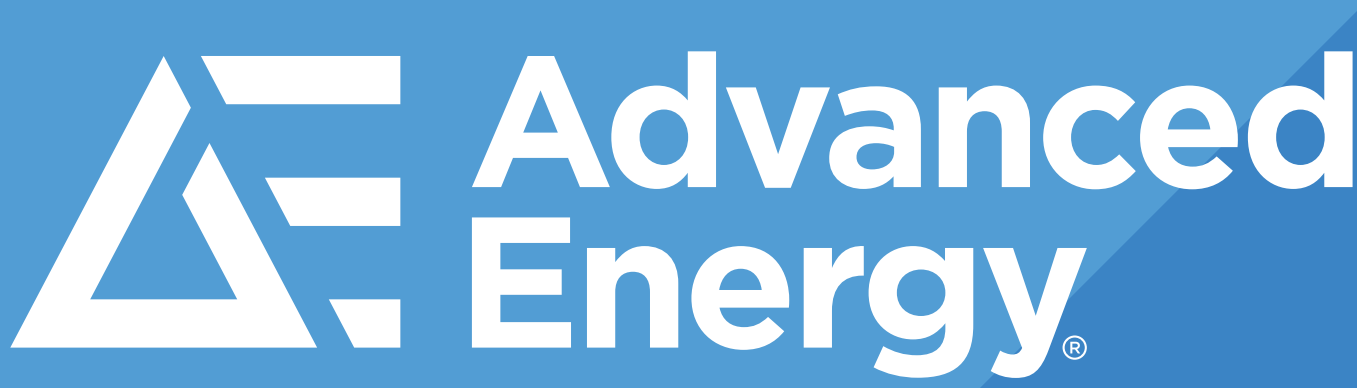

SLE06 	6 W 100K Hours MTBF Up to 78% Efficiency 1.67 x 2.89 x 1.21 in. 4.2 to 12 Vdc Models Medical and ITE Safety Compliant DoE Level VI & CoC Version 5, Tier 2 Efficiency	ME10/TE10 	10 W >1,000K Hours MTBF >10 Year E-Cap Life Desk-Top 1.85 x 3.31 x 1.22 in. Wall-Mount 1.85 x 3.31 x 1.50 in. >87% Typical Efficiency 5, 5.9, 7.5, 9, 12, 15, 24 Vdc Models Medical and ITE Safety Compliant	SLE12 	12 W 100K Hours MTBF Up to 83% Efficiency 1.19 x 2.99 x 1.90 in. 5 to 24 Vdc Models Medical and ITE Safety Compliant DoE Level VI & CoC Version 5, Tier 2 Efficiency
SLE18 	18 W 100K Hours MTBF Up to 85% Efficiency 1.18 x 3.47 x 2.24 in. 5 to 24 Vdc Models Medical and ITE Safety Compliant DoE Level VI & CoC Version 5, Tier 2 Efficiency	ME20/TE20 	20 W >1,000K Hours MTBF >7 Year E-Cap Life Desk-Top 1.85 x 3.31 x 1.22 in. Wall-Mount 1.85 x 3.31 x 1.50 in. >87% Typical Efficiency 5, 5.9, 7.5, 9, 12, 15, 24, 48 Vdc Models Medical and ITE Safety Compliant	SLE24 	24 W 100K Hours MTBF Up to 87% Efficiency 1.18 x 3.47 x 2.24 in. 7 to 52 Vdc Models Medical and ITE Safety Compliant DoE Level VI & CoC Version 5, Tier 2 Efficiency
ME30/TE30 	30 W >1,000K Hours MTBF >8 Year E-Cap Life Desk-Top 2.13 x 3.76 x 1.22 in. Wall-Mount 2.17 x 3.78 x 1.32 in. >87%, Typical Efficiency 5, 9, 12, 15, 12, 18, 24, 48Vdc models Medical and ITE Safety Compliant	GE30D 	30 W Dual Output 5.2 x 2.4 x 1.3 in IEC 62368-1 USB A port + DC output and connector DoE Level VI & CoC Version 5, Tier 2 Efficiency	SLE36 	36 W 100K Hours MTBF Up to 88% Efficiency 1.30 x 3.81 x 1.99 in. 9 to 36 Vdc Models Medical and ITE Safety Compliant DoE Level VI & CoC Version 5, Tier 2 Efficiency
ME40/TE40 	40 W >1,000K Hours MTBF >8 Year E-Cap Life Desk-Top 2.13 x 3.76 x 1.22 in. Wall-Mount 2.17 x 3.78 x 1.32 in. >87%, Typical Efficiency 5, 12, 18, 24Vdc models Medical and ITE Safety Compliant	SLE48 	48 W 100K Hours MTBF Up to 88% Efficiency 1.30 x 3.81 x 1.99 in. 9 to 36 Vdc Models Medical and ITE Safety Compliant DoE Level VI & CoC Version 5, Tier 2 Efficiency	ME60/TE60 	60 W >250K Hours MTBF >7 Year E-Cap Life 2.67 x 4.25 x 1.29 in. >88% Typical Efficiency 5, 9, 12, 15, 18, 24, 48 Vdc Models Medical and ITE Safety Compliant
SLE60SPD 	60 W (3A) USB-C output port 4th Edition EMC Compliance Wall-plug and Desktop Versions Medically-approved USB-PD Efficiency Level VI, CoC Tier II compliant Medical and ITE Safety Compliant	SLE65 	65 W 100K Hours MTBF Up to 88% Efficiency 1.30 x 3.81 x 1.99 in. 9 to 36 Vdc Models DoE Level VI & CoC Version 5, Tier 2 Efficiency	ME90/TE90 	90 W >250K Hours MTBF >7 Year E-Cap Life 2.58 x 5.9 x 1.34 in. >88% Typical Efficiency 12, 15, 18, 24 Vdc Models Medical and ITE Safety Compliant
SLE90 	90 W 100K Hours MTBF Up to 88% Efficiency 1.30 x 3.81 x 1.99 in. 9 to 36 Vdc Models Medical and ITE Safety Compliant DoE Level VI & CoC Version 5, Tier 2 Efficiency	GE150 	150 W >250K Hours MTBF >7 Year E-Cap Life 4.25 x 8.43 x 1.85 in. 12, 15, 24, 28, 48 Vdc Models DoE Level VI & CoC Version 5, Tier 2 Efficiency	ME240/TE240 	240 W >250K Hours MTBF >7 Year E-Cap Life 4.25 x 8.43 x 1.85 in. 12, 15, 24, 28, 48 Vdc Models Medical and ITE Safety Compliant DoE Level VI & CoC Version 5, Tier 2 Efficiency

KT1001

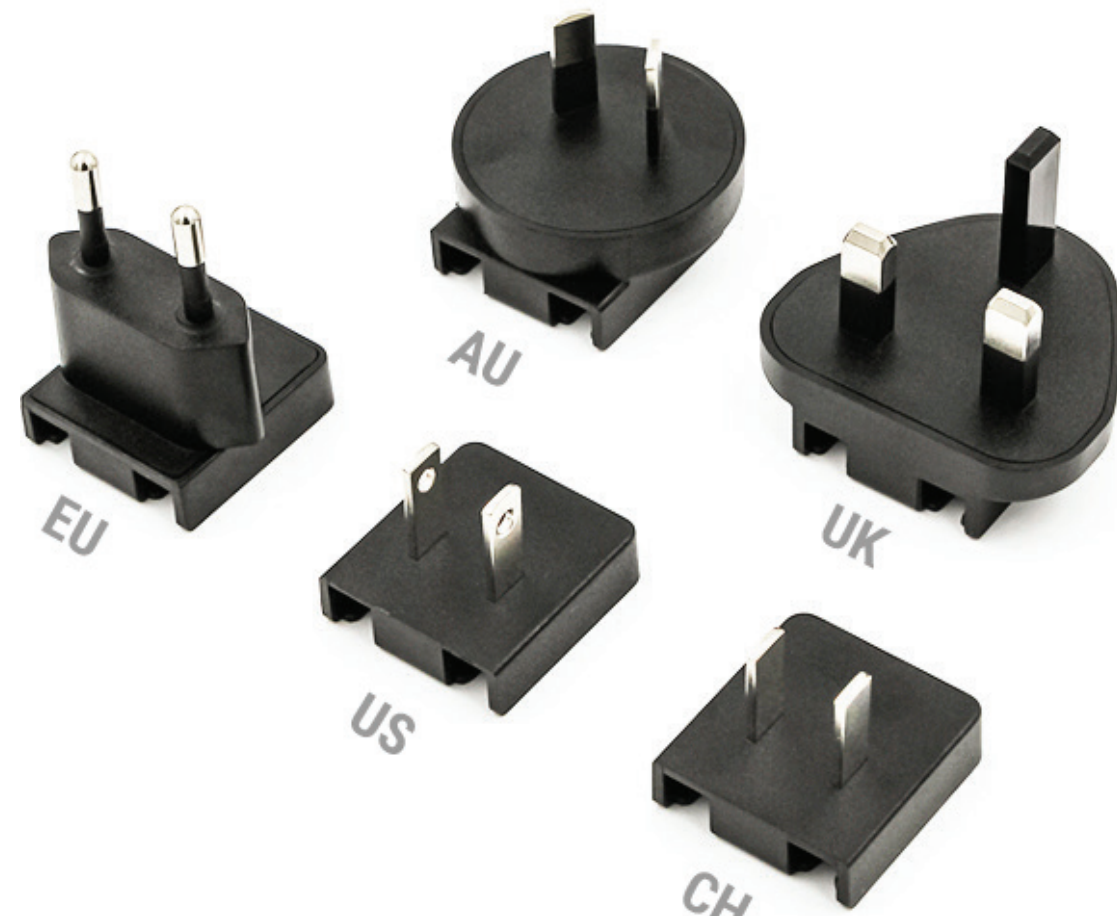

Bladekit for SLE Series

KT1001AU - Australia
KT1001CH - China
KT1001EU - European
KT1001US - United States
KT1001UK - United Kingdom
KT1001K - EU, UK, and AU
KT1001A - EU, UK, AU, US

Alternate output connectors are available

Consult with representative for configuration option including input and output connectors, color, special labeling and additional certifications