

MAN & MACHINE

Mighty O'Mouse

Oil-Resistant Industrial Mouse



Oil Resistant, Top Quality

The Mighty O'Mouse is a fully sealed rugged industrial mouse engineered to handle the most challenging environments. Based on our Mighty Mouse, this mouse is fully-functional and sealed. You'll find glide and touch instantly familiar. The innovative five-button design allows for scrolling and selecting with ease. The Mighty O'Mouse is impervious to dust, oil, and grease, making it the perfect solution for dusty, dirty, greasy, oily environments.

Factory and Machine Shop Ready

Use standard industrial cleaners or wash with soap and water. The Mighty O'Mouse is proudly born in the USA. Don't compromise. Accept no less than the new standard in oil resistant mice - Mighty O'Mouse.




Sealed, Waterproof, & Immersible. Oil-Safe.



Sealed Low Profile Design - Easily clean and disinfect between the keys with an EPA-registered wipe.



Smart cable: Non-standard cable lengths available.

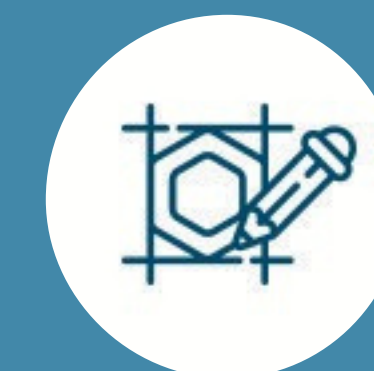

Private Label - Add a one-color custom logo



Built to Last



Born in the USA

Man & Machine, Inc.

✉ info@mmimd.com 🌐 www.man-machine.com

☎ 301.341.4900

Mighty O'Mouse

Oil-Resistant Industrial Mouse

Benefits of a Sealed Keyboard/Mouse

1. Fully Sealed & Seamless
2. Built to Hold Up to Rigors of Harsh Environments & Multiple Users
3. Designed for Use in Dusty Dirty Environments
4. Designed for Use in Dusty, Dirty, Oily Environments
5. Avoid Anti-Microbial Additives



Features

- 5-Button Mouse - Left/Right, Up/Down Scrolling & Scroll Lock
- Sealed, Waterproof, & Immersible
- Oil-Safe
- Cleanable with harsh disinfectants
- 1-Year Warranty

Specifications

- Material: Oil-Safe Silicone Rubber, 100% Latex-Free
- Size: 5" x 2.5" x 1.3" (125 x 63 x 34 mm)
- Weight: 4.95 ounces (142 g)
- Cable Length: 6 ft (1.83 m)
- Storage Temperature: -20° to 70°C (-4° to 158°F)
- Operating Temperature: 0° to 70°C (32° to 158°F)
- Platform: Windows, Mac & Linux
- Voltage: 5 Volt
- Protection Rating: IP68
- Connector: USB

Colors

- Black

Man & Machine, Inc.

✉ info@mmimd.com 🌐 www.man-machine.com

☎ 301.341.4900